

Product datasheet

Specifications



"Wall mounted steel enclosure, PanelSeT S3D, plain door, without mounting plate, 600x500x250mm, IP66, IK10"

Local distributor code:
392866402

NSYS3D6525

EAN Code: 3606480159275

Main

Range	PanelSeT
Product name	PanelSeT S3D
Application	Multi-purpose
Category	Compact enclosure
Enclosure nominal height	600 mm
Enclosure nominal width	500 mm
Enclosure nominal depth	250 mm
Door type	Plain
Mounting plate description	Without mounting plate
Type of gland plate	Standard
Installation accessory type	Wall-mounting
Device composition	1 body 1 door 1 lock 1 cable gland plate

Complementary

body type	Gutter-shaped front rail double sheet thickness Single piece body
Number of doors	Front face: 1 door(s)
Door opening side	Reversible (120 °)
Lock type	3 points lock, 3 mm double-bar
Accessibility for operation	Front
Removable parts	Door by hinges Cable gland plate by screws
Material	Steel
Surface finish	Epoxy-polyester powder
Colour	Grey (RAL 7035)
Standards	IEC 62208
Product certifications	BV DNV cUL UL GL
Net weight	13.466 kg

Environment

NEMA degree of protection	NEMA 4X/13
IK degree of protection	IK10 conforming to IEC 62262
IP degree of protection	IP66 conforming to IEC 60529

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	29.500 cm
Package 1 Width	51.500 cm
Package 1 Length	61.500 cm
Package 1 Weight	13.400 kg
Unit Type of Package 2	P12
Number of Units in Package 2	18
Package 2 Height	199.000 cm
Package 2 Width	80.000 cm
Package 2 Length	120.000 cm
Package 2 Weight	255.000 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

Mercury Free

Rohs Exemption Information Yes

Certifications & Standards

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)


China Rohs Regulation [China RoHS declaration](#)
Product out of China RoHS scope. Substance declaration for your information

Environmental Disclosure [Product Environmental Profile](#)

Circularity Profile No need of specific recycling operations

Technical Illustration

Dimensions

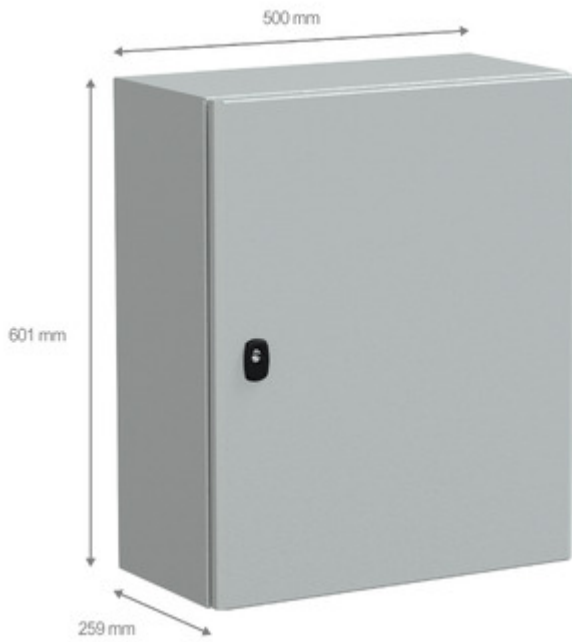

Offer Marketing Illustration

Product benefits / Features



Sturdy components' protection

Earthing studs included

Large choice of dimensions & accessories

Quality & aesthetics

Easy to equip
Easy to maintain

Reusable eco-friendly packaging