

# Product datasheet

Specifications



"Wall mounted steel enclosure, PanelSeT S3D, plain door, with mounting plate, 500x500x200mm, IP66, IK10"

Local distributor code:  
392866295

NSYS3D5520P

EAN Code: 3606480159381

## Main

Range	PanelSeT
Product name	PanelSeT S3D
Application	Multi-purpose
Category	Compact enclosure
Enclosure nominal height	500 mm
Enclosure nominal width	500 mm
Enclosure nominal depth	200 mm
Door type	Plain
Mounting plate description	Plain
Type of gland plate	Standard
Installation accessory type	Wall-mounting
Device composition	1 body 1 mounting plate 1 door with lock 1 cable gland plate

## Complementary

body type	Single piece body Gutter-shaped front rail double sheet thickness
Number of doors	Front face: 1 door(s)
Door opening side	Reversible (120 °)
Lock type	3 mm double-bar lock
Accessibility for operation	Front
Removable parts	Door by hinges Cable gland plate by screws Mounting plate by fixing element
Material	Enclosure: steel Mounting plate: galvanised steel
Surface finish	Enclosure: epoxy-polyester powder
Colour	Enclosure: grey (RAL 7035)
Standards	IEC 62208
Product certifications	UL GL cUL DNV BV

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

---

Net weight	13 kg
------------	-------

## Environment

---

NEMA degree of protection	NEMA 4X/13
---------------------------	------------

---

IK degree of protection	IK10 conforming to IEC 62262
-------------------------	------------------------------

---

IP degree of protection	IP66 conforming to IEC 60529
-------------------------	------------------------------

## Packing Units

---

Unit Type of Package 1	PCE
------------------------	-----

---

Number of Units in Package 1	1
------------------------------	---

---

Package 1 Height	25.000 cm
------------------	-----------

---

Package 1 Width	51.500 cm
-----------------	-----------

---

Package 1 Length	51.500 cm
------------------	-----------

---

Package 1 Weight	12.902 kg
------------------	-----------

---

Unit Type of Package 2	PAM
------------------------	-----

---

Number of Units in Package 2	24
------------------------------	----

---

Package 2 Height	169.000 cm
------------------	------------

---

Package 2 Width	100.000 cm
-----------------	------------

---

Package 2 Length	120.000 cm
------------------	------------

---

Package 2 Weight	322.000 kg
------------------	------------

## Contractual warranty

---

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

## Well-being performance

Mercury Free

RoHS Exemption Information Yes

## Certifications & Standards

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)

China Rohs Regulation [China RoHS declaration](#)  
Product out of China RoHS scope. Substance declaration for your information


Environmental Disclosure [Product Environmental Profile](#)

Circularity Profile No need of specific recycling operations

Technical Illustration

Dimensions

---

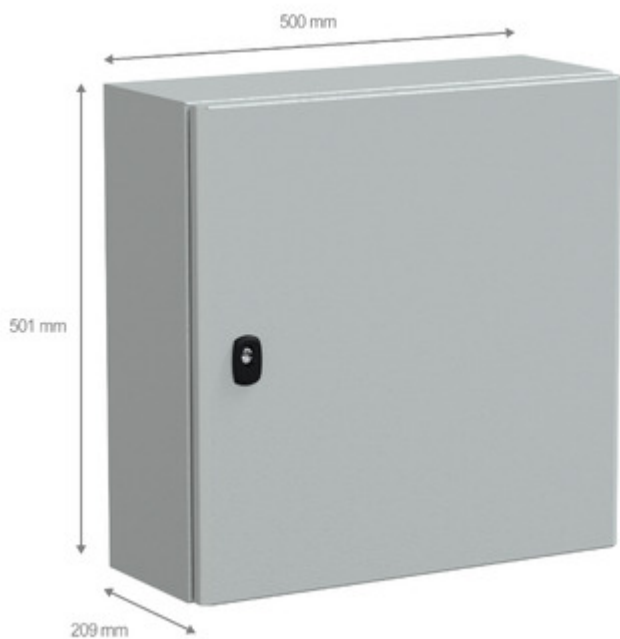

Offer Marketing Illustration

Product benefits / Features

---



Sturdy components' protection

Earthing studs included

Large choice of dimensions & accessories

Quality & aesthetics

Easy to equip  
Easy to maintain

Reusable eco-friendly packaging