


# AOUS3/008 Datasheet

Product Name // USB 3.2 Gen2 Active Optical Cable, A male to C male PVC jacket no screws, right angle 8m

[View Product Page](#)

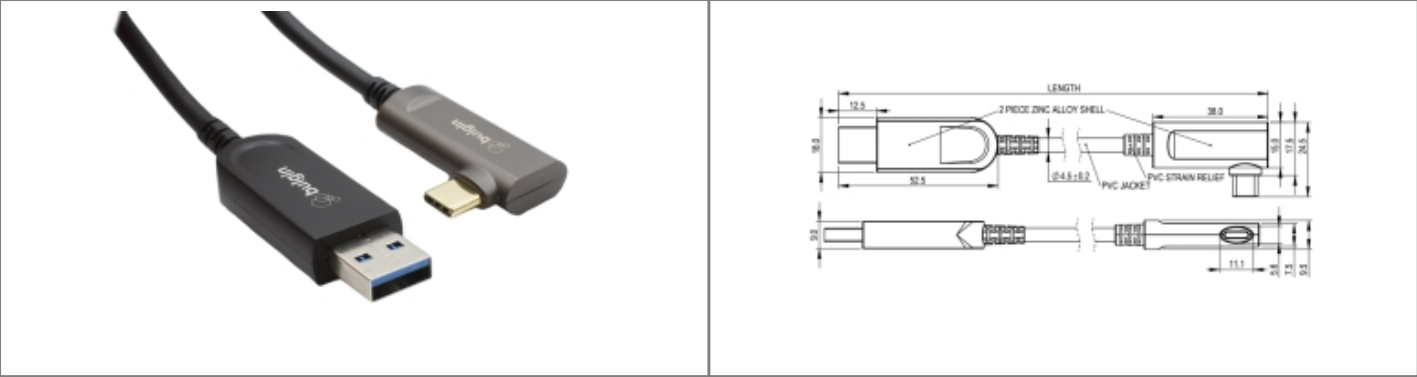

// Product Description:

- USB 3.2 Gen2 Active Optical Cable, A male to C male PVC jacket no screws, right angle
- Cable length 8m
- 90-degree angle design for limited space connections
- Up to 10Gbps

// General Information:

|                            |                 |
|----------------------------|-----------------|
| Product Display Title:     | USB 3.2 Cable   |
| Product Family:            | Data Connectors |
| Product Series:            | AO Series USB   |
| Body Colour:               | Black           |
| Body Material:             | Zinc Alloy      |
| Body Material Type:        | Metal           |
| Cable Length:              | 8m              |
| Contact Type:              | Plug Contact    |
| Data Cable Type:           | USB 3.2 Gen 2   |
| Durability:                | 1000            |
| Fibre Mode:                | Multimode       |
| Flamability Rating:        | VW-1            |
| Function:                  | USB 3.2 Cable   |
| Max Operating Temperature: | 50°C            |
| Min Operating Temperature: | 0°C             |
| Rohs Compliant:            | Yes             |
| Sheath Colour:             | Black           |
| Sheath Material:           | PVC             |
| Voltage Max:               | 5.5V            |

// Product PDF Links

[AO Series USB product data](#)

// Product 3D CAD Model Links

[AOUS3/0083D CAD Model](#)



Have a question or project enquiry you'd like to talk to us about?



[Click Here To Contact Us](#)