

## Hi-D22F2P2F 21.5" 100 Hz IPS Monitor



- IPS technology, 178° ultra-wide view screen.
- 8 bit LVDS FHD (1920 × 1080) display.
- 100 Hz refresh rate, more fluid and life-like video.
- Ultra-thin device body with ultra-thin border for 3 sides.
- 3D noise reduction.
- Low blue light design for eye care.
- Dual interface of HDMI and VGA.
- Support VESA wall mount.

## ▪ Specification

Display	
Screen Size	21.5 inch
Active Display Area	527.04 (H) mm × 296.46 (V) mm
Resolution	1920 × 1080
Backlight	E-LED
Pixel Pitch	0.2745 (H) mm × 0.2745 (V) mm
Brightness	250 cd/m <sup>2</sup>
Viewing Angle	178° (H)/178° (V)
Color Depth	8 bit, 16.7 M
Contrast Ratio	4000:1
Response Time	7 ms
Refresh Rate	100 Hz
Haze	Haze 25%
Reliability	7 × 16H
Color Gamut	72% NTSC
Interface	
Video & Audio Input	HDMI 1.4 × 1, VGA × 1
Video & Audio Output	Audio Out × 1
Power	
Power Supply	DC 12 V, 2.0 A
Power Consumption	≤ 24 W
Standby Consumption	≤ 0.5 W
Working Environment	
Working Temperature	0 °C to 40 °C (32 °F to 104 °F)
Working Humidity	20% RH to 90% RH (Non-Condensing)
Storage Temperature	-20 °C to 60 °C (-4 °F to 140 °F)
Storage Humidity	10% RH to 90% RH (Non-Condensing)
General	
Casing Material	Plastic
VESA	75 mm × 75 mm (4 - M4 × 6 mm)
Bezel Width	2.38 mm (top/left/right), 21.55 mm (bottom)
Product Dimensions (W × H × D)	With base: 493.26 (W) mm × 369.12 (H) mm × 162.75 (D) mm 19.42 (W) inch × 14.53 (H) inch × 6.41 (D) inch Without base: 493.26 (W) mm × 290.14 (H) mm × 42.68 (D) mm 19.42 (W) inch × 11.42 (H) inch × 1.68 (D) inch
Package Dimensions (W × H × D)	598 (W) mm × 391 (H) mm × 106 (D) mm 23.54 (W) inch × 15.39 (H) inch × 4.17 (D) inch
Net Weight	2.0 ± 0.5 kg (4.4 ± 1.1 lb)
Gross Weight	3.2 ± 0.5 kg (7.1 ± 1.1 lb)
Packing List	Monitor × 1, Base component × 1, Power adapter (12 V, 2 A) × 1, HDMI cable (1.5 m) × 1, User manual × 1, Multilingual manual × 1
Remarks	The base is included by default. The product appearance and parameters in this specification may vary from your actual device. Please consult our local sales staff for further information

### Physical Interface


Interface	Description	Interface	Description
HDMI 1.4	HDMI 1.4 digital signal input interface	VGA	VGA analog signal input interface
Audio out	3.5 mm Audio output interface	DC	DC 12 V 2.0 A input interface



### Available Model

Hi-D22F2P2F

### Dimension

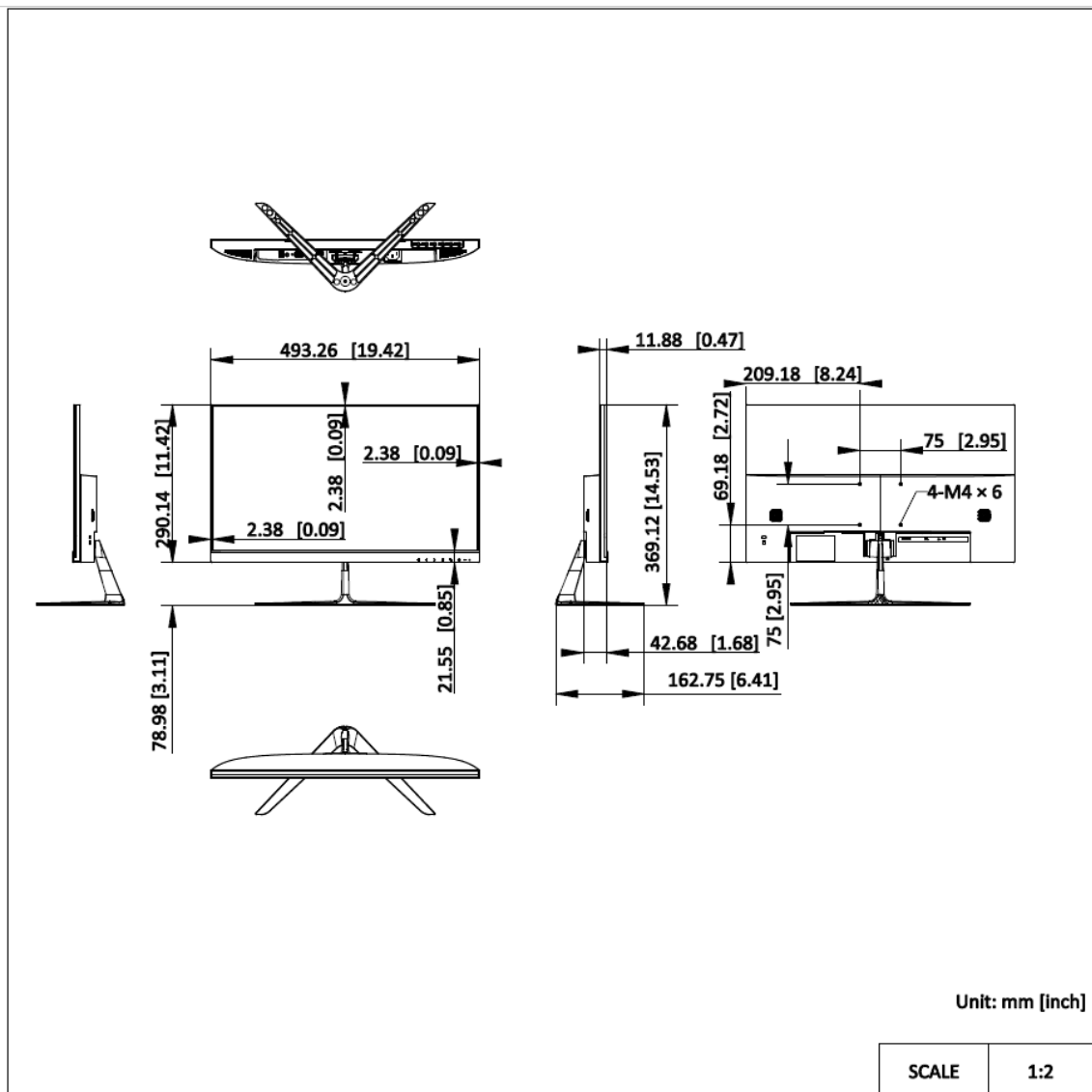

- **Accessory**
- **Optional**

**DS-DM1940W**  
**Wall-mounted Bracket**



# HiLook

## Headquarters

No.555 Qianmo Road, Binjiang District,  
Hangzhou 310051, China  
T +86-571-8807-5998  
Technical Support: support@hikvision.com

Follow us on social media to get the latest product and solution information.

