


2:1 Normal Wall Heatshrink Tubing **multicomp** PRO

**RoHS
Compliant**

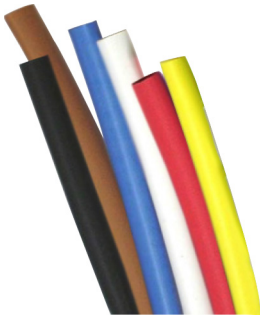

Applications

The heat shrink tubing is manufactured with modified radiation cross-linked polyolefin. The specially designed halogen free formulation makes the tubing very flexible and shrink at lower temperature. Suitable for applications where temperature sensitive components protection, e.g. PVC jacketed wire and cable and quick shrinkage is required. It has good mechanical and electrical performances.

Characteristics:

- Halogen Free
- Operating temperature -55°C to +125°C
- Min. shrink temperature 70°C
Full recovery temperature: 120°C
- Shrink Ratio 2:1
- Meets Sony-SS-00259
- Standard Colours: Black, Brown, Blue, White, Red, Yellow

Technical Data:

Property	Test Method	Standard Value
Tensile Strength	ASTM D2671	≥10.4 Mpa
Ultimate Elongation	ASTM D2671	≥200%
Longitudinal Shrinkage	UL 224	±5%
Heat Aging Tensile Strength Ultimate Elongation	158°C, 168hrs	≥7.3 Mpa ≥100%
Heat shock	250°C, 4hrs	No cracking, No dripping
Flammability	FMVSS302	Pass
Dielectric Strength	ASTM D150	≥15 kV/mm
Volume Resistivity	ASTM D2671	≥1x10 ¹⁴ Ωcm
Copper Stability	UL224	Pass
Copper Corrosion	UL224	No corrosion

Product Dimensions:

Size		As supplied		After Recovery	
Inch	mm	Internal diameter (mm)	Wall thickness (mm)	Internal diameter Max(mm)	Wall thickness Nom(mm)
1/16	1.6	1.5 ±0.2	0.2 ±0.05	0.65	0.36 ±0.1
3/32	2.4	2.5 ±0.2	0.2 ±0.05	1	0.45 ±0.1
1/8	3.2	3.5 ±0.2	0.2 ±0.05	1.5	0.45 ±0.1
3/16	4.8	5 ±0.2	0.28 ±0.05	2.3	0.56 ±0.1

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
sg.element14.com/b/multicomp-pro

multicomp PRO

2:1 Normal Wall Heatshrink Tubing **multicomp** PRO

Size		As supplied		After Recovery	
Inch	mm	Internal diameter (mm)	Wall thickness (mm)	Internal diameter Max(mm)	Wall thickness Nom(mm)
1/4	6.4	6.5 ±0.2	0.28 ±0.05	3	0.56 ±0.1
3/8	9.5	9.5 ±0.3	0.3 ±0.08	4.5	0.56 ±0.1
1/2	12.7	12.5 ±0.3	0.3 ±0.08	6	0.56 ±0.1
3/4	19	19 ±0.5	0.35 ±0.1	9	0.7 ±0.1
1	25.4	26 ±0.5	0.45 ±0.12	12.5	0.9 ±0.15
1-1/2	38.1	41.5 ±1	0.5 ±0.12	20	1 ±0.15
2	50.8	≥50	0.5 ±0.15	25	1.1 ±0.2

Part Number Table

Description	Reel Length	Part Number	Description	Reel Length	Part Number
Heatshrink Tubing Normal Wall 2:1 Black 1.6mm	100m	13633	Heatshrink Tubing Normal Wall 2:1 Red 19mm	100m	13673
Heatshrink Tubing Normal Wall 2:1 Black 2.4mm	100m	13634	Heatshrink Tubing Normal Wall 2:1 Red 25.4mm	50m	13674
Heatshrink Tubing Normal Wall 2:1 Black 3.2mm	100m	13635	Heatshrink Tubing Normal Wall 2:1 Red 38.1mm	50m	13675
Heatshrink Tubing Normal Wall 2:1 Black 4.8mm	100m	13636	Heatshrink Tubing Normal Wall 2:1 Red 50.8mm	25m	13676
Heatshrink Tubing Normal Wall 2:1 Black 6.4mm	100m	13637	Heatshrink Tubing Normal Wall 2:1 Red 1.6mm	5m	15045
Heatshrink Tubing Normal Wall 2:1 Black 9.5mm	100m	13638	Heatshrink Tubing Normal Wall 2:1 Red 2.4mm	5m	15046
Heatshrink Tubing Normal Wall 2:1 Black 12.7mm	100m	13639	Heatshrink Tubing Normal Wall 2:1 Red 3.2mm	5m	15047
Heatshrink Tubing Normal Wall 2:1 Black 19mm	100m	13640	Heatshrink Tubing Normal Wall 2:1 Red 4.8mm	5m	15048
Heatshrink Tubing Normal Wall 2:1 Black 25.4mm	50m	13641	Heatshrink Tubing Normal Wall 2:1 Red 6.4mm	5m	15049
Heatshrink Tubing Normal Wall 2:1 Black 38.1mm	50m	13642	Heatshrink Tubing Normal Wall 2:1 Red 9.5mm	5m	15050
Heatshrink Tubing Normal Wall 2:1 Black 50.8mm	25m	13643	Heatshrink Tubing Normal Wall 2:1 Red 12.7mm	5m	15051
Heatshrink Tubing Normal Wall 2:1 Black 1.6mm	5m	13644	Heatshrink Tubing Normal Wall 2:1 Red 19mm	5m	15052
Heatshrink Tubing Normal Wall 2:1 Black 2.4mm	5m	13645	Heatshrink Tubing Normal Wall 2:1 Red 25.4mm	5m	15053
Heatshrink Tubing Normal Wall 2:1 Black 3.2mm	5m	13646	Heatshrink Tubing Normal Wall 2:1 Red 38.1mm	5m	15054
Heatshrink Tubing Normal Wall 2:1 Black 4.8mm	5m	13647	Heatshrink Tubing Normal Wall 2:1 Red 50.8mm	5m	15055
Heatshrink Tubing Normal Wall 2:1 Black 6.4mm	5m	13648	Heatshrink Tubing Normal Wall 2:1 Yellow 2.4mm	100m	13678
Heatshrink Tubing Normal Wall 2:1 Black 9.5mm	5m	13649	Heatshrink Tubing Normal Wall 2:1 Yellow 3.2mm	100m	13679
Heatshrink Tubing Normal Wall 2:1 Black 12.7mm	5m	13650	Heatshrink Tubing Normal Wall 2:1 Yellow 4.8mm	100m	13680
Heatshrink Tubing Normal Wall 2:1 Black 19mm	5m	13651	Heatshrink Tubing Normal Wall 2:1 Yellow 6.4mm	100m	13681
Heatshrink Tubing Normal Wall 2:1 Black 25.4mm	5m	13652	Heatshrink Tubing Normal Wall 2:1 Yellow 9.5mm	100m	13682
Heatshrink Tubing Normal Wall 2:1 Black 38.1mm	5m	13653	Heatshrink Tubing Normal Wall 2:1 Yellow 12.7mm	100m	13683
Heatshrink Tubing Normal Wall 2:1 Black 50.8mm	5m	13654	Heatshrink Tubing Normal Wall 2:1 Yellow 19mm	100m	13684
Heatshrink Tubing Normal Wall 2:1 Red 1.6mm	100m	13666	Heatshrink Tubing Normal Wall 2:1 Yellow 25.4mm	50m	13685
Heatshrink Tubing Normal Wall 2:1 Red 2.4mm	100m	13667	Heatshrink Tubing Normal Wall 2:1 Yellow 38.1mm	50m	13686
Heatshrink Tubing Normal Wall 2:1 Red 3.2mm	100m	13668	Heatshrink Tubing Normal Wall 2:1 Yellow 50.8mm	25m	13687
Heatshrink Tubing Normal Wall 2:1 Red 4.8mm	100m	13669	Heatshrink Tubing Normal Wall 2:1 Yellow 1.6mm	5m	15056
Heatshrink Tubing Normal Wall 2:1 Red 6.4mm	100m	13670	Heatshrink Tubing Normal Wall 2:1 Yellow 2.4mm	5m	15057
Heatshrink Tubing Normal Wall 2:1 Red 9.5mm	100m	13671	Heatshrink Tubing Normal Wall 2:1 Yellow 3.2mm	5m	15058
Heatshrink Tubing Normal Wall 2:1 Red 12.7mm	100m	13672	Heatshrink Tubing Normal Wall 2:1 Yellow 4.8mm	5m	15059

Newark.com/multicomp-pro
 Farnell.com/multicomp-pro
 sg.element14.com/b/multicomp-pro

multicomp PRO

2:1 Normal Wall Heatshrink Tubing **multicomp** PRO

Description	Reel Length	Part Number	Description	Reel Length	Part Number
Heatshrink Tubing Normal Wall 2:1 Yellow 6.4mm	5m	15060	Heatshrink Tubing Normal Wall 2:1 Blue 3.2mm	5m	15080
Heatshrink Tubing Normal Wall 2:1 Yellow 9.5mm	5m	15061	Heatshrink Tubing Normal Wall 2:1 Blue 4.8mm	5m	15081
Heatshrink Tubing Normal Wall 2:1 Yellow 12.7mm	5m	15062	Heatshrink Tubing Normal Wall 2:1 Blue 6.4mm	5m	15082
Heatshrink Tubing Normal Wall 2:1 Yellow 19mm	5m	15063	Heatshrink Tubing Normal Wall 2:1 Blue 9.5mm	5m	15083
Heatshrink Tubing Normal Wall 2:1 Yellow 25.4mm	5m	15064	Heatshrink Tubing Normal Wall 2:1 Blue 12.7mm	5m	15084
Heatshrink Tubing Normal Wall 2:1 Yellow 38.1mm	5m	15065	Heatshrink Tubing Normal Wall 2:1 Blue 19mm	5m	15085
Heatshrink Tubing Normal Wall 2:1 Yellow 50.8mm	5m	15066	Heatshrink Tubing Normal Wall 2:1 Blue 25.4mm	5m	15086
Heatshrink Tubing Normal Wall 2:1 White 1.6mm	100m	13688	Heatshrink Tubing Normal Wall 2:1 Blue 38.1mm	5m	15087
Heatshrink Tubing Normal Wall 2:1 White 2.4mm	100m	13689	Heatshrink Tubing Normal Wall 2:1 Blue 50.8mm	5m	15088
Heatshrink Tubing Normal Wall 2:1 White 3.2mm	100m	13690	Heatshrink Tubing Normal Wall 2:1 Brown 1.6mm	100m	13721
Heatshrink Tubing Normal Wall 2:1 White 4.8mm	100m	13691	Heatshrink Tubing Normal Wall 2:1 Brown 2.4mm	100m	13722
Heatshrink Tubing Normal Wall 2:1 White 6.4mm	100m	13692	Heatshrink Tubing Normal Wall 2:1 Brown 3.2mm	100m	13723
Heatshrink Tubing Normal Wall 2:1 White 9.5mm	100m	13693	Heatshrink Tubing Normal Wall 2:1 Brown 4.8mm	100m	13724
Heatshrink Tubing Normal Wall 2:1 White 12.7mm	100m	13694	Heatshrink Tubing Normal Wall 2:1 Brown 6.4mm	100m	13725
Heatshrink Tubing Normal Wall 2:1 White 19mm	100m	13695	Heatshrink Tubing Normal Wall 2:1 Brown 9.5mm	100m	13726
Heatshrink Tubing Normal Wall 2:1 White 25.4mm	50m	13696	Heatshrink Tubing Normal Wall 2:1 Brown 12.7mm	100m	13727
Heatshrink Tubing Normal Wall 2:1 White 38.1mm	50m	13697	Heatshrink Tubing Normal Wall 2:1 Brown 19mm	100m	13728
Heatshrink Tubing Normal Wall 2:1 White 50.8mm	25m	13698	Heatshrink Tubing Normal Wall 2:1 Brown 25.4mm	50m	13729
Heatshrink Tubing Normal Wall 2:1 White 1.6mm	5m	15067	Heatshrink Tubing Normal Wall 2:1 Brown 38.1mm	50m	13730
Heatshrink Tubing Normal Wall 2:1 White 2.4mm	5m	15068	Heatshrink Tubing Normal Wall 2:1 Brown 50.8mm	25m	13731
Heatshrink Tubing Normal Wall 2:1 White 3.2mm	5m	15069	Heatshrink Tubing Normal Wall 2:1 Brown 1.6mm	5m	15100
Heatshrink Tubing Normal Wall 2:1 White 4.8mm	5m	15070	Heatshrink Tubing Normal Wall 2:1 Brown 2.4mm	5m	15101
Heatshrink Tubing Normal Wall 2:1 White 6.4mm	5m	15071	Heatshrink Tubing Normal Wall 2:1 Brown 3.2mm	5m	15102
Heatshrink Tubing Normal Wall 2:1 White 9.5mm	5m	15072	Heatshrink Tubing Normal Wall 2:1 Brown 4.8mm	5m	15103
Heatshrink Tubing Normal Wall 2:1 White 12.7mm	5m	15073	Heatshrink Tubing Normal Wall 2:1 Brown 6.4mm	5m	15104
Heatshrink Tubing Normal Wall 2:1 White 19mm	5m	15074	Heatshrink Tubing Normal Wall 2:1 Brown 9.5mm	5m	15105
Heatshrink Tubing Normal Wall 2:1 White 25.4mm	5m	15075	Heatshrink Tubing Normal Wall 2:1 Brown 12.7mm	5m	15106
Heatshrink Tubing Normal Wall 2:1 White 38.1mm	5m	15076	Heatshrink Tubing Normal Wall 2:1 Brown 19mm	5m	15107
Heatshrink Tubing Normal Wall 2:1 White 50.8mm	5m	15077	Heatshrink Tubing Normal Wall 2:1 Brown 25.4mm	5m	15108
Heatshrink Tubing Normal Wall 2:1 Blue 1.6mm	100m	13699	Heatshrink Tubing Normal Wall 2:1 Brown 38.1mm	5m	15109
Heatshrink Tubing Normal Wall 2:1 Blue 2.4mm	100m	13700	Heatshrink Tubing Normal Wall 2:1 Brown 50.8mm	5m	15110
Heatshrink Tubing Normal Wall 2:1 Blue 3.2mm	100m	13701	Heatshrink Tubing Normal Wall 2:1, Black, 1.2mm	1.2m	PP002706
Heatshrink Tubing Normal Wall 2:1 Blue 4.8mm	100m	13702	Heatshrink Tubing Normal Wall 2:1, Black, 1.6mm	1.2m	PP002707
Heatshrink Tubing Normal Wall 2:1 Blue 6.4mm	100m	13703	Heatshrink Tubing Normal Wall 2:1, Black, 2.4mm	1.2m	PP002708
Heatshrink Tubing Normal Wall 2:1 Blue 9.5mm	100m	13704	Heatshrink Tubing Normal Wall 2:1, Black, 3.2mm	1.2m	PP002709
Heatshrink Tubing Normal Wall 2:1 Blue 12.7mm	100m	13705	Heatshrink Tubing Normal Wall 2:1, Black, 4.8mm	1.2m	PP002710
Heatshrink Tubing Normal Wall 2:1 Blue 19mm	100m	13706	Heatshrink Tubing Normal Wall 2:1, Black, 6.4mm	1.2m	PP002711
Heatshrink Tubing Normal Wall 2:1 Blue 25.4mm	50m	13707	Heatshrink Tubing Normal Wall 2:1, Black, 7.9mm	1.2m	PP002712
Heatshrink Tubing Normal Wall 2:1 Blue 38.1mm	50m	13708	Heatshrink Tubing Normal Wall 2:1, Black, 9.5mm	1.2m	PP002713
Heatshrink Tubing Normal Wall 2:1 Blue 50.8mm	25m	13709	Heatshrink Tubing Normal Wall 2:1, Black, 12.7mm	1.2m	PP002714
Heatshrink Tubing Normal Wall 2:1 Blue 1.6mm	5m	15078	Heatshrink Tubing Normal Wall 2:1, Black, 19mm	1.2m	PP002715
Heatshrink Tubing Normal Wall 2:1 Blue 2.4mm	5m	15079	Heatshrink Tubing Normal Wall 2:1, Black, 25.4mm	1.2m	PP002716

Newark.com/multicomp-pro
 Farnell.com/multicomp-pro
 sg.element14.com/b/multicomp-pro

multicomp PRO

2:1 Normal Wall Heatshrink Tubing **multicomp** PRO

Description	Reel Length	Part Number	Description	Reel Length	Part Number
Heatshrink Tubing Normal Wall 2:1, Black, 38.1mm	1.2m	PP002718	Heatshrink Tubing Normal Wall 2:1, White, 4.8mm	1.2m	PP002760
Heatshrink Tubing Normal Wall 2:1, Black, 50.8mm	1.2m	PP002719	Heatshrink Tubing Normal Wall 2:1, White, 6.4mm	1.2m	PP002761
Heatshrink Tubing Normal Wall 2:1, Clear, 1.2mm	1.2m	PP002720	Heatshrink Tubing Normal Wall 2:1, White, 9.5mm	1.2m	PP002762
Heatshrink Tubing Normal Wall 2:1, Clear, 1.6mm	1.2m	PP002721	Heatshrink Tubing Normal Wall 2:1, White, 12.7mm	1.2m	PP002763
Heatshrink Tubing Normal Wall 2:1, Clear, 2.4mm	1.2m	PP002722	Heatshrink Tubing Normal Wall 2:1, White, 19mm	1.2m	PP002764
Heatshrink Tubing Normal Wall 2:1, Clear, 3.2mm	1.2m	PP002723	Heatshrink Tubing Normal Wall 2:1, White, 25.4mm	1.2m	PP002765
Heatshrink Tubing Normal Wall 2:1, Clear, 4.8mm	1.2m	PP002724	Heatshrink Tubing Normal Wall 2:1, White, 38.1mm	1.2m	PP002766
Heatshrink Tubing Normal Wall 2:1, Clear, 6.4mm	1.2m	PP002725	Heatshrink Tubing Normal Wall 2:1, White, 50.8mm	1.2m	PP002767
Heatshrink Tubing Normal Wall 2:1, Clear, 9.5mm	1.2m	PP002726	Heatshrink Tubing Normal Wall 2:1, Blue, 1.2mm	1.2m	PP002768
Heatshrink Tubing Normal Wall 2:1, Clear, 12.7mm	1.2m	PP002727	Heatshrink Tubing Normal Wall 2:1, Blue, 1.6mm	1.2m	PP002769
Heatshrink Tubing Normal Wall 2:1, Clear, 19mm	1.2m	PP002728	Heatshrink Tubing Normal Wall 2:1, Blue, 2.4mm	1.2m	PP002770
Heatshrink Tubing Normal Wall 2:1, Clear, 25.4mm	1.2m	PP002729	Heatshrink Tubing Normal Wall 2:1, Blue, 3.2mm	1.2m	PP002771
Heatshrink Tubing Normal Wall 2:1, Clear, 38.1mm	1.2m	PP002730	Heatshrink Tubing Normal Wall 2:1, Blue, 4.8mm	1.2m	PP002772
Heatshrink Tubing Normal Wall 2:1, Clear, 50.8mm	1.2m	PP002731	Heatshrink Tubing Normal Wall 2:1, Blue, 6.4mm	1.2m	PP002773
Heatshrink Tubing Normal Wall 2:1, Red, 1.2mm	1.2m	PP002732	Heatshrink Tubing Normal Wall 2:1, Blue, 9.5mm	1.2m	PP002774
Heatshrink Tubing Normal Wall 2:1, Red, 1.6mm	1.2m	PP002733	Heatshrink Tubing Normal Wall 2:1, Blue, 12.7mm	1.2m	PP002775
Heatshrink Tubing Normal Wall 2:1, Red, 2.4mm	1.2m	PP002734	Heatshrink Tubing Normal Wall 2:1, Blue, 19mm	1.2m	PP002776
Heatshrink Tubing Normal Wall 2:1, Red, 3.2mm	1.2m	PP002735	Heatshrink Tubing Normal Wall 2:1, Blue, 25.4mm	1.2m	PP002777
Heatshrink Tubing Normal Wall 2:1, Red, 4.8mm	1.2m	PP002736	Heatshrink Tubing Normal Wall 2:1, Blue, 38.1mm	1.2m	PP002778
Heatshrink Tubing Normal Wall 2:1, Red, 6.4mm	1.2m	PP002737	Heatshrink Tubing Normal Wall 2:1, Blue, 50.8mm	1.2m	PP002779
Heatshrink Tubing Normal Wall 2:1, Red, 9.5mm	1.2m	PP002738	Heatshrink Tubing Normal Wall 2:1, Brown, 1.2mm	1.2m	PP002780
Heatshrink Tubing Normal Wall 2:1, Red, 12.7mm	1.2m	PP002739	Heatshrink Tubing Normal Wall 2:1, Brown, 1.6mm	1.2m	PP002781
Heatshrink Tubing Normal Wall 2:1, Red, 19mm	1.2m	PP002740	Heatshrink Tubing Normal Wall 2:1, Brown, 2.4mm	1.2m	PP002782
Heatshrink Tubing Normal Wall 2:1, Red, 25.4mm	1.2m	PP002741	Heatshrink Tubing Normal Wall 2:1, Brown, 3.2mm	1.2m	PP002783
Heatshrink Tubing Normal Wall 2:1, Red, 38.1mm	1.2m	PP002742	Heatshrink Tubing Normal Wall 2:1, Brown, 4.8mm	1.2m	PP002784
Heatshrink Tubing Normal Wall 2:1, Red, 50.8mm	1.2m	PP002743	Heatshrink Tubing Normal Wall 2:1, Brown, 6.4mm	1.2m	PP002785
Heatshrink Tubing Normal Wall 2:1, Yellow, 1.2mm	1.2m	PP002744	Heatshrink Tubing Normal Wall 2:1, Brown, 9.5mm	1.2m	PP002786
Heatshrink Tubing Normal Wall 2:1, Yellow, 1.6mm	1.2m	PP002745	Heatshrink Tubing Normal Wall 2:1, Brown, 12.7mm	1.2m	PP002787
Heatshrink Tubing Normal Wall 2:1, Yellow, 2.4mm	1.2m	PP002746	Heatshrink Tubing Normal Wall 2:1, Brown, 19mm	1.2m	PP002788
Heatshrink Tubing Normal Wall 2:1, Yellow, 3.2mm	1.2m	PP002747	Heatshrink Tubing Normal Wall 2:1, Brown, 25.4mm	1.2m	PP002789
Heatshrink Tubing Normal Wall 2:1, Yellow, 4.8mm	1.2m	PP002748	Heatshrink Tubing Normal Wall 2:1, Brown, 38.1mm	1.2m	PP002790
Heatshrink Tubing Normal Wall 2:1, Yellow, 6.4mm	1.2m	PP002749	Heatshrink Tubing Normal Wall 2:1, Brown, 50.8mm	1.2m	PP002791
Heatshrink Tubing Normal Wall 2:1, Yellow, 9.5mm	1.2m	PP002750	Heatshrink Tubing Normal Wall 2:1, Green, 1.2mm	1.2m	PP002792
Heatshrink Tubing Normal Wall 2:1, Yellow, 12.7mm	1.2m	PP002751	Heatshrink Tubing Normal Wall 2:1, Green, 1.6mm	1.2m	PP002793
Heatshrink Tubing Normal Wall 2:1, Yellow, 19mm	1.2m	PP002752	Heatshrink Tubing Normal Wall 2:1, Green, 2.4mm	1.2m	PP002794
Heatshrink Tubing Normal Wall 2:1, Yellow, 25.4mm	1.2m	PP002753	Heatshrink Tubing Normal Wall 2:1, Green, 3.2mm	1.2m	PP002795
Heatshrink Tubing Normal Wall 2:1, Yellow, 38.1mm	1.2m	PP002754	Heatshrink Tubing Normal Wall 2:1, Green, 4.8mm	1.2m	PP002796
Heatshrink Tubing Normal Wall 2:1, Yellow, 50.8mm	1.2m	PP002755	Heatshrink Tubing Normal Wall 2:1, Green, 6.4mm	1.2m	PP002797
Heatshrink Tubing Normal Wall 2:1, White, 1.2mm	1.2m	PP002756	Heatshrink Tubing Normal Wall 2:1, Green, 9.5mm	1.2m	PP002798
Heatshrink Tubing Normal Wall 2:1, White, 1.6mm	1.2m	PP002757	Heatshrink Tubing Normal Wall 2:1, Green, 12.7mm	1.2m	PP002799
Heatshrink Tubing Normal Wall 2:1, White, 2.4mm	1.2m	PP002758	Heatshrink Tubing Normal Wall 2:1, Green, 19mm	1.2m	PP002800
Heatshrink Tubing Normal Wall 2:1, White, 3.2mm	1.2m	PP002759	Heatshrink Tubing Normal Wall 2:1, Green, 25.4mm	1.2m	PP002801

Newark.com/multicomp-pro
 Farnell.com/multicomp-pro
 sg.element14.com/b/multicomp-pro

multicomp PRO

2:1 Normal Wall Heatshrink Tubing **multicomp** PRO

Description	Reel Length	Part Number
Heatshrink Tubing Normal Wall 2:1, Green, 38.1mm	1.2m	PP002802
Heatshrink Tubing Normal Wall 2:1, Green, 50.8mm	1.2m	PP002803
Heatshrink Tubing Normal Wall 2:1, Grey, 1.2mm	1.2m	PP002804
Heatshrink Tubing Normal Wall 2:1, Grey, 1.6mm	1.2m	PP002805
Heatshrink Tubing Normal Wall 2:1, Grey, 2.4mm	1.2m	PP002806
Heatshrink Tubing Normal Wall 2:1, Grey, 3.2mm	1.2m	PP002807
Heatshrink Tubing Normal Wall 2:1, Grey, 4.8mm	1.2m	PP002808
Heatshrink Tubing Normal Wall 2:1, Grey, 6.4mm	1.2m	PP002809
Heatshrink Tubing Normal Wall 2:1, Grey, 9.5mm	1.2m	PP002810
Heatshrink Tubing Normal Wall 2:1, Grey, 12.7mm	1.2m	PP002811
Heatshrink Tubing Normal Wall 2:1, Grey, 19mm	1.2m	PP002812
Heatshrink Tubing Normal Wall 2:1, Grey, 25.4mm	1.2m	PP002813
Heatshrink Tubing Normal Wall 2:1, Grey, 38.1mm	1.2m	PP002814
Heatshrink Tubing Normal Wall 2:1, Grey, 50.8mm	1.2m	PP002815
Heatshrink Tubing Normal Wall 2:1, Green/Yellow, 1.6mm	1.2m	PP002816
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 2.4mm	1.2m	PP002817
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 3.2mm	1.2m	PP002818
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 4.8mm	1.2m	PP002819
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 6.4mm	1.2m	PP002820
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 9.5mm	1.2m	PP002821
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 12.7mm	1.2m	PP002822
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 19mm	1.2m	PP002823
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 25.4mm	1.2m	PP002824
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 38.1mm	1.2m	PP002825
Heatshrink Tubing Normal Wall 2:1, Grey/Yellow, 50.8mm	1.2m	PP002826

Important Notice : This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro
 Farnell.com/multicomp-pro
 sg.element14.com/b/multicomp-pro

multicomp PRO