



Part Number : [1731120046](#)


Product Description : FCT Coaxial Contact, Male, Straight, Solder Cable Termination, 50 Ohms, 1.30µm Gold Plating, for RG-178BU, RG-196AU, or RG-404U Cable

Series Number : 173112

Status : Active

Product Category : D-Sub Contacts

Engineering Number : FMX005P102

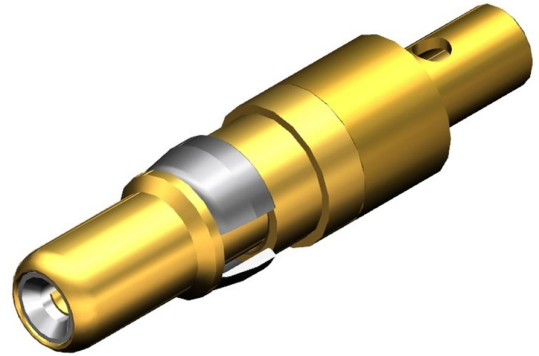

Documents & Resources

Drawings

[1731120046_sd.pdf](#)

3D Models and Design Files

[1731120046_stp.zip](#)

Specifications

[2195600660-000.pdf](#)

[1731120009-PK-000.pdf](#)

[2195600660-000.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Not Relevant |
| China RoHS | |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Reviewed per IEC 61249-2-21 |
| REACH SVHC | Contains Lead per D(2024)4144-DC (27 June 2024) |
| EU RoHS | Compliant with Exemption 6(c) per EU 2015/863 |

Multiple Part Product Compliance Statements

- Eu RoHS

- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

| | |
|--------------|---|
| Status | Active |
| Category | D-Sub Contacts |
| Series | 173112 |
| Description | FCT Coaxial Contact, Male, Straight, Solder Cable Termination, 50 Ohms, 1.30µm Gold Plating, for RG-178BU, RG-196AU, or RG-404U Cable |
| Contact Type | Coaxial |
| Magnetic | Yes |
| Product Name | FCT Products |
| Type | Mixed Layout |
| UPC | 889056322874 |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 2.0A |
| Impedance | 50Ω |

Physical

| | |
|--------------------------------|------------------|
| Durability (mating cycles max) | 200 |
| Gender | Male |
| Material - Contact | Copper Alloy |
| Material - Plating Mating | Gold over Nickel |
| Material - Plating Termination | Gold over Nickel |
| Net Weight | 1.400/g |
| Orientation | Straight |

| | |
|-------------------------------|-----------------------------|
| Packaging Type | Bag |
| Plating min - Mating | 1.300µm |
| Plating min - Termination | 0.200µm |
| Temperature Range - Operating | -55° to +135°C |
| Termination Style | Solder/Crimp |
| Wire/Cable Type | RG-178BU, RG-196AU, RG-404U |

Use with Part(s)

| Description | Part Number |
|-------------|-----------------------------|
| Use With | FCT Mixed Layout Connectors |

Application Tooling

Global

| Description | Part Number |
|--|-------------------|
| FCT Hand Crimp Tool, Hex Die, Open Frame | <u>1731121732</u> |
| FCT Locator for Coaxial Contacts | <u>1731121735</u> |
| FCT Removal Tool for Size 8 Contacts | <u>1731121747</u> |