 


acer



TravelMate P2 16

Intel® Core™ i5-1335U processor
16" WUXGA (1920 X 1200) 16:10 IPS Display¹
TCO Certified²






TravelMate P2 16

The durable and sustainably designed TravelMate P2 features improved performance, business-grade security, and a highly refined user experience for work and video conferencing that makes it one of the best value laptops for small businesses.



A New Level of Usability

Get work done with ease thanks to the 16:10 display that offers more vertical screen real estate. This small business laptop also features a 180° hinge, large touch pad, numeric keypad, and keys with a 1.55mm travel distance for better usability.

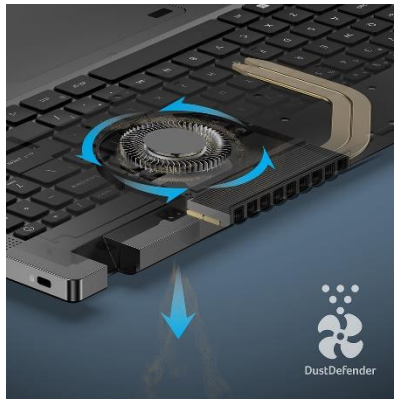

Guaranteed Performance

With a 13th Gen Intel® Core™ i5 CPU¹, 16GB¹ DDR4 memory, this laptop offers all the performance needed to keep up with your work. It also comes with Acer Dust Defender that minimizes dust accumulation in the device for consistent performance.



Strong on Security

Secure your data and work without worry. This secured-core PC features discrete TPM 2.0, fingerprint reader¹ and IR camera¹ for secure login. The added privacy shutter reduces the risk of unauthorized access of your webcam.



Optimized Video Conferencing

The HD¹ webcam help you look your best in any lighting environment. Video calls are a breeze with dual microphones optimized with Acer PurifiedVoice's AI-powered noise-reduction and upward facing speakers with DTS® Audio.



Staying Connected

Stay connected no matter where you are with Wi-Fi 6E¹ connectivity. Connect all your peripherals with this laptop's wide variety of ports including a Type C Thunderbolt 4 port supporting 40Gbps data transfer and dual 4K displays.



Designed for Sustainability

This TCO certified² small business laptop uses PCR³ plastic, an OceanGlass™¹ touchpad made from ocean-bound plastics, and 100% recycled packaging materials. This laptop's lifespan is further increased with MIL-STD-810H durability and reinforced IO ports.

TravelMate Solutions

Be it at home, work, or at the frontline, TravelMate's streamlined selection of laptops offer solutions for the new challenges that professionals face today.



Collaboration

No matter where you are in the world, make use of adaptable collaborative tools to easily get things done together with your colleagues.




Productivity

Combining next-gen hardware, intuitive designs, and highly functional applications, you'll be able to get more done in less time than ever before.



Security & Privacy

Protect your privacy and your data from unwanted access with the latest security features and designs.

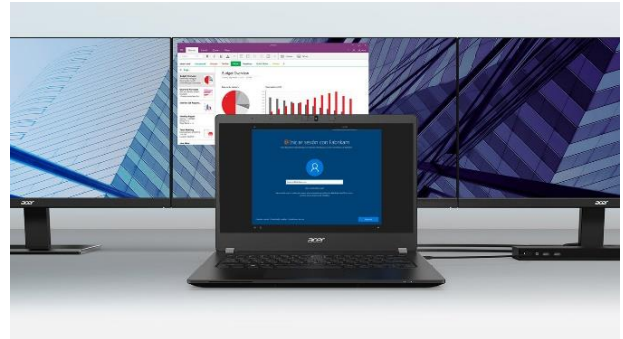

Organizational Efficiency

Optimize resources and save your IT team from undue hassles with highly efficient applications to deploy new devices, secure them, enable remote access, and more.



Added Protections

Combine military grade durability, reinforced IO ports, and more for not only a high-performing professional laptop, but one that overcomes all the challenges that work and life throw at it.



Sustainability

Acer is committed to creating a green revolution within the technology industry. The TCO certified TravelMate products contain post-consumer recycled plastic, and use 100% plastic-free and recyclable packaging. We ensure that the products we offer are environmentally responsible as well improve your ESG performance.

SPECIFICATIONS

TravelMate P2 16

TMP216-51-TCO-NX.B1BEK.009

Operating system¹	Windows 11 Pro	Dimensions and weight^{1, 8, 9}	Dimensions: 358.5 (W) x 260 (D) x 19.9/22.9 (H) mm (14.11 x 10.24 x 0.78/0.9 inches) with Plastic A Cover Weight: 1.87 kg (4.12 lbs.) with 3-cell battery pack, one SSD
CPU and chipset¹	Intel® Core™ i5-1335U processor	Power adapter and battery^{1, 10}	Power adapter: USB Type-C 65 WPD AC adapter Battery: • 50 Wh 3-cell Li-ion battery
Memory^{1,2,3,4}	Dual-channel DDR4 SDRAM support 16 GB of DDR4 system memory Memory Frequency: Up to 3200 MT/s	Keyboard:	Acer backlit keyboard with international language support, with indicators of CapsLock and F4/Microphone mute
Display⁵	16.0" display with IPS (In-Plane Switching) technology, WUXGA 1920 x 1200, Acer ComfyView™ LED-backlit TFT LCD • 16:10 aspect ratio, color gamut NTSC 45% • Wide viewing angle up to 170 degrees • Mercury free, environment friendly	Touchpad:	Multi-gesture secure touchpad, supporting two-finger scroll; pinch; gestures to open Cortana, Action Center, multitasking; Fingerprint application commands (1) Windows Hello Certification (2) Microsoft Precision Touchpad certification
Graphics⁶	Intel® Iris® X ^e Graphics	Input and output	USB Type-C™ port, supporting: • USB4® 40Gbps • Thunderbolt™ 4 • USB charging 5 V; 3 A • DC-in port 19 V; 65 W Two USB Standard-A ports, supporting: • One port for USB 3.2 Gen 1 featuring power off USB charging • One port for USB 3.2 Gen 1 microSD™ Card reader SmartCard reader slot Ethernet (RJ-45) port DC-in jack for AC adapter HDMI® 2.0 port with HDCP support
Audio	• Acer Purified.Voice technology with AI noise reduction in dual built-in microphones. • DTS® Audio, featuring optimized bass response and micro-speaker distortion prevention • Acer TrueHarmony technology for lower distortion, wider frequency range, headphone-like audio and powerful sound	Windows Desktop Apps¹¹	• Acer Control Center • Acer Product Registration • Quick Access
Storage^{1,7}	Solid state drive: • 256 GB, PCIe Gen4, 16 Gb/s, NVMe	System compliance¹²	• ENERGY STAR® • Wi-Fi®
Webcam¹	UFC with: • T-Type HD camera • Compatible with Windows • 1280 x 720 resolution • 720p HD video at 30 fps with Temporal Noise Reduction • Blue Glass lens • Knowles Dual Mic (33 mm + 33 mm) • 78 x 3.2 (5.2) x 3 mm	Warranty	One-year International Travelers Warranty (ITW)
Wireless and networking¹	WLAN: • Intel® Wireless Wi-Fi 6E AX211 • 802.11a/b/g/n/ac/ax wireless LAN • Band: 2.4 GHz, 5 GHz and 6 GHz • 2x2 MU-MIMO technology • Supports Bluetooth® 5.1 or above • Support vPro / Support CNVi interface LAN: • Gigabit Ethernet	Quality and reliability tests	Temperature and humidity Hinge life Weight and pressure Acoustics Spillage Free drop Shock and vibration Electrostatic discharge immunity Keyboard-switch life MTBF (mean time between failures) Military Reliability Test: MIL-STD 810H / MIL-STD 810F
Security¹	• Acer Bio-Protection fingerprint solution, featuring computer protection and Windows Hello Certification • Discrete Trusted Platform Module (TPM) solution • BIOS user, supervisor, HDD passwords • Kensington lock slot • Acer ProShield Plus security manager includes: (1) Data Protection: File & Folder Encryption and Decryption, Personal Secure Drive (2) Data Removal: File Shredder (3) Security Alert: Invalid Access Alert, Security Report		

- Specifications vary depending on model.
- Shared system memory may be allocated to support graphics, depending on system memory size and other factors. Actual system memory available to the operating system will be reduced by any memory used by the graphics solution and resources required by the operating environment.
- Memory speed may vary, depending on the CPU, chipset or memory fitted.
- A 64-bit operating system is required to enjoy the ultimate performance of 4 GB or higher memory.
- All brands and product names mentioned herein include trademarks of their respective companies and are used solely to describe or identify the products.
- Not all features indicated are supported on all SKUs.
- 1 GB is 1 billion bytes, 1 TB is 1000 GB. Actual formatted capacity is less and may vary depending on preloaded materials and operating environment. Acer Recovery Management uses a portion of the stated hard disk capacity as dedicated backup space.
- Minor variations in system dimensions are possible due to the manufacturing process.
- Weight may vary depending on product configuration, vendor components, manufacturing variability, and selected options.
- Actual battery life may vary considerably by specifications, depending on product model, configuration, applications, power management settings, operating conditions, and features utilized. Performance variation also arises based on components in use, which includes but is not limited to the processor, RAM capacity, storage, display and resolution, etc.
- Bundled software may vary depending on hardware configuration, OS and regional availability.

In a continuing effort to improve the quality of our products, information in this document is subject to change without notice. Images shown are only representations of some of the configurations available for this model. Availability may vary depending on region.
As a phenomenon known to thin-film transistors (TFTs), liquid crystal displays (LCDs) commonly exhibit a small number of discoloration dots, as so-called "non-conforming pixels." This phenomenon is a limitation of TFT LCD technology, not a product defect, and as such is not covered by Acer's warranty.
© 2023. All rights reserved.
Microsoft and Windows are registered trademarks of Microsoft Corporation.
Ultrabook, Celeron, Celeron Inside, Core Inside, Intel, Intel Logo, Intel Arc graphics, Intel Atom, Intel Atom Inside, Intel Core, Intel Inside, Intel Inside Logo, Intel vPro, Intel Evo, Pentium, Pentium Inside, vPro Inside, Xeon, Xeon Phi, Xeon Phi Inside, Intel Agilio, Arria, Cyclone, Movidius, eASIC, Ethernet, Iris, Killer, MAX, Select Solutions, Si Photonics, Stratix, Tofino, and Intel Optane are trademarks of Intel Corporation or its subsidiaries.

About Acer
Founded in 1976, Acer is one of the world's top ICT companies with a presence in more than 160 countries. As Acer evolves with the industry and changing lifestyles, it is focused on enabling a world where hardware, software and services will fuse with one another, creating ecosystems and opening up new possibilities for consumers and businesses alike. Acer's 7,500 employees are dedicated to the research, design, marketing, sale, and support of products and solutions that break barriers between people and technology. Please visit www.acer.com for more information.



Recommended Accessory



Acer USB Type-C Dock III



4,500 Lumens SVGA Projector X1128HK



24" ZeroFrame FHD Monitor VA2 series

What We Offer



Innovative Solutions*

Acer offers a range of unique services that simplifies everything from purchasing your product with Acer Device as a Service (DaaS) and trade-in programs to deploying and managing your device with Acer Office Manager and Acer ProShield Plus.



Guaranteed Peace of Mind*

All TravelMate products include a minimum one-year International Travelers Warranty. Depending on your region, you can extend this warranty for up to 5 years while also taking advantage of additional coverage for the battery, data recovery, media retention, and insurance for accidental damage.



Award-winning Service*

Our award-winning service model allows us to quickly and efficiently support your business to meet challenges head-on. With more than 3,000 service and repair centers in 160 countries and regions, Acer for Business provides round-the-clock access to skilled and experienced technicians across the globe.