

0413-214-1205 ✓ ACTIVE

DEUTSCH | DEUTSCH HD30, DEUTSCH HD


TE Internal #: 0413-214-1205

Keying Plug, PBT GF30, Yellow, -55 – 125 °C [-67 – 257 °F]

[View on TE.com >](#)



Connectors > Connector Accessories > Connector Seals & Cavity Plugs > DEUTSCH Sealing Plugs

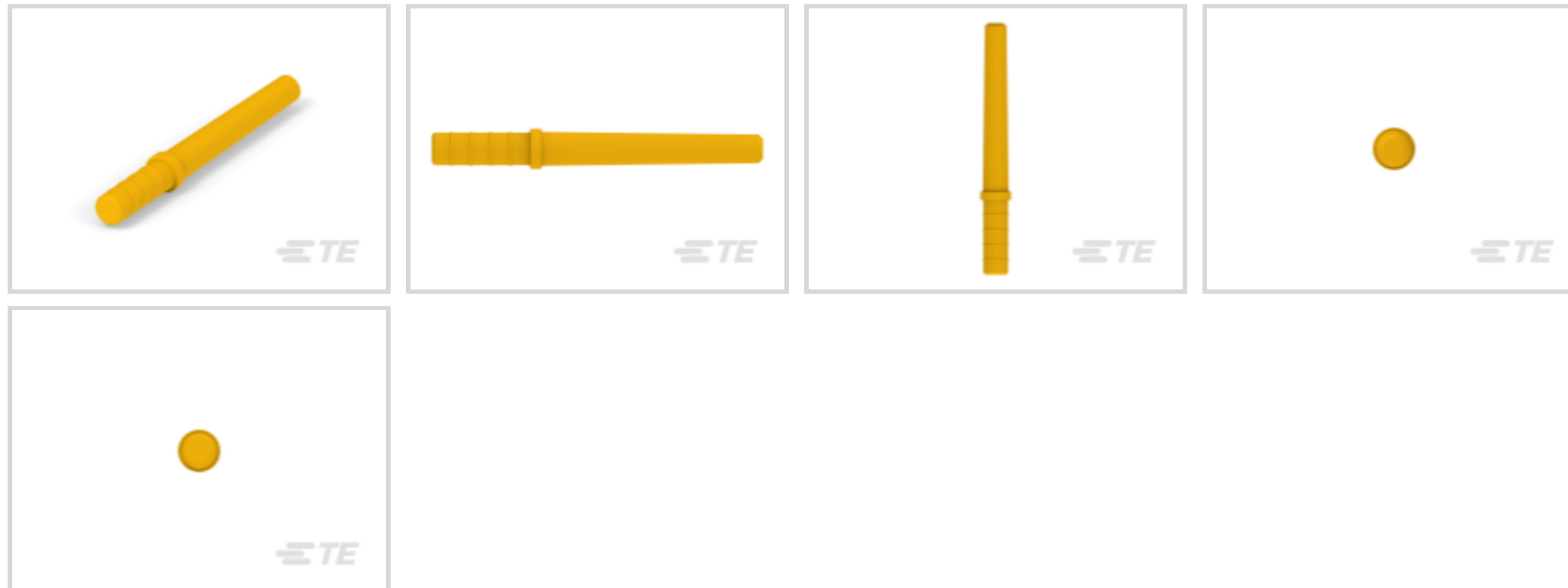

Connector Seal & Plug Type: **Keying Plug**

Primary Product Material: **PBT GF30**

Primary Product Color: **Yellow**

Operating Temperature (Max): **125 °C [257 °F]**

Contains Lubricant: **No**

[All DEUTSCH Sealing Plugs \(10\)](#)

## Features

### Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

### Packaging Features

Packaging Method	Box
------------------	-----

### Product Type Features

Connector Seal & Plug Type	Keying Plug
----------------------------	-------------

### Body Features

Primary Product Material	PBT GF30
--------------------------	----------

Primary Product Color	Yellow
-----------------------	--------

### Usage Conditions

Operating Temperature (Max)	125 °C[257 °F]
-----------------------------	----------------

Operating Temperature Range	-55 – 125 °C[-67 – 257 °F]
-----------------------------	----------------------------

### Other

Contains Lubricant	No
--------------------	----

EU RoHS Compliance	Compliant
--------------------	-----------

EU ELV Compliance	Compliant
-------------------	-----------

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
------------------------------	-----------

EU ELV Directive 2000/53/EC	Compliant
-----------------------------	-----------

China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
---	---

EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
--	---

 
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
-----------------	--


 
 

Solder Process Capability	Not reviewed for solder process capability
---------------------------	--

### Product Compliance Disclaimer







This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



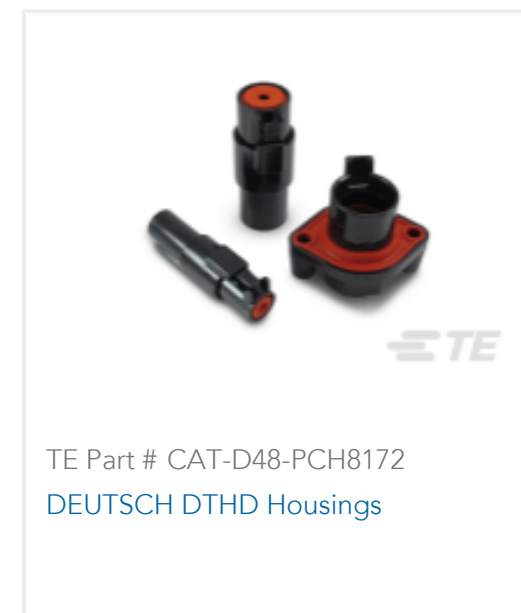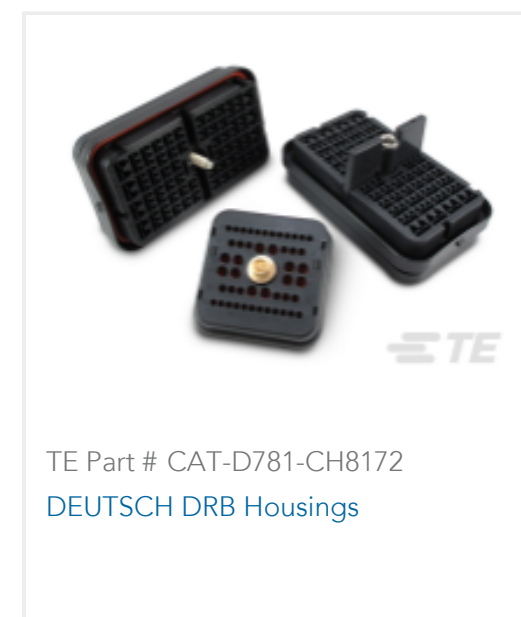

Also in the Series | **DEUTSCH HD**

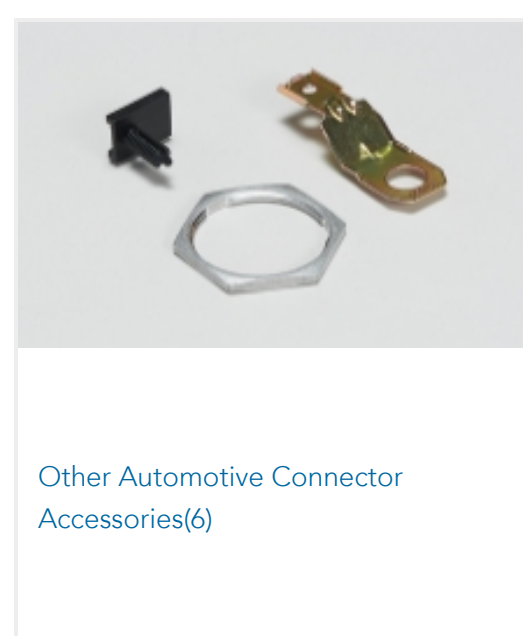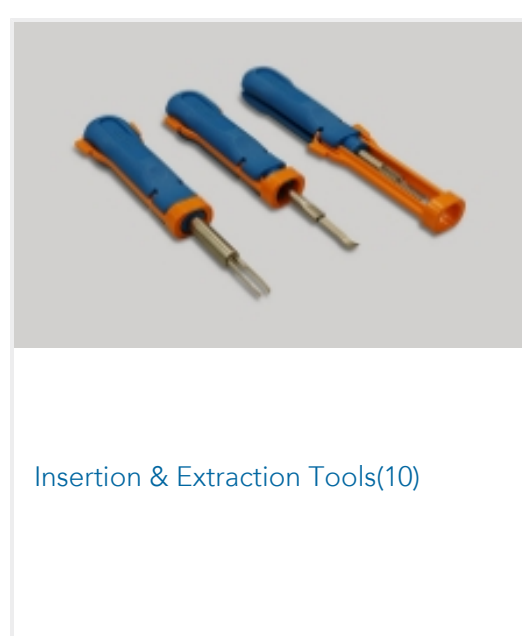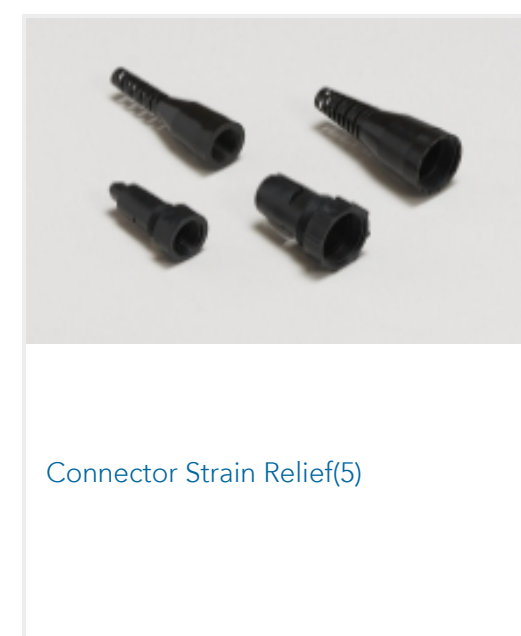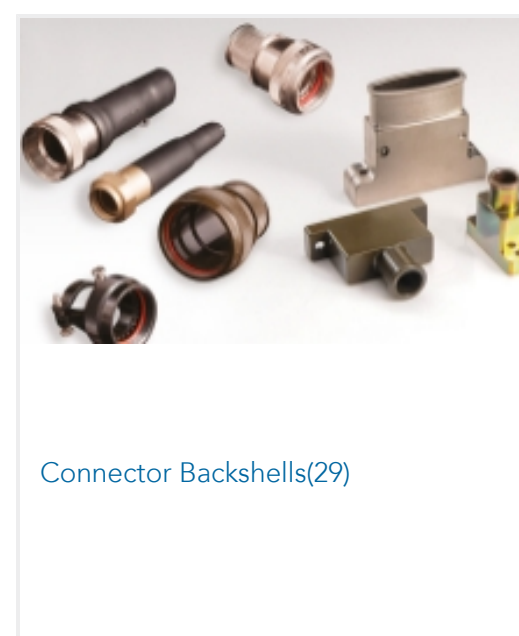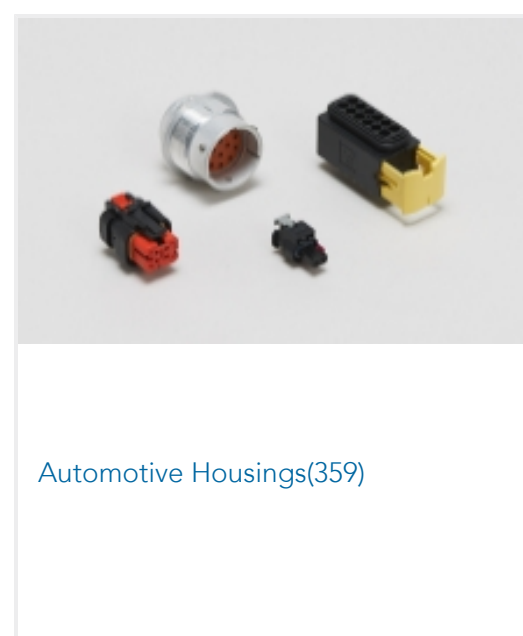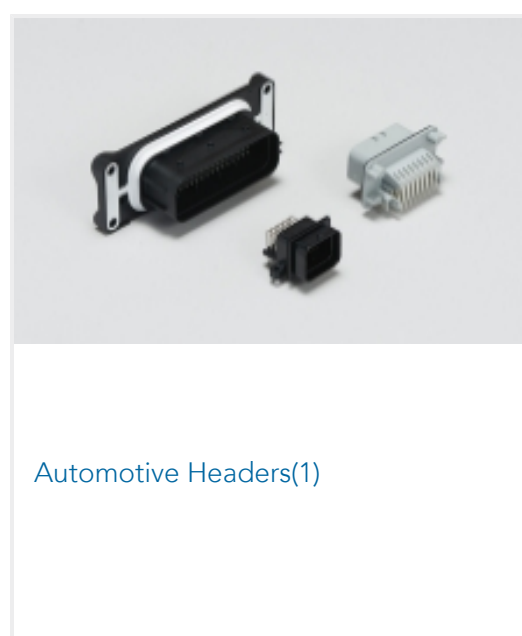

Also in the Series | **DEUTSCH HD30**



Automotive Connector Caps & Covers (14)



Automotive Housings(359)



Connector Seals & Cavity Plugs(11)



Connector Strain Relief(5)



Insertion & Extraction Tools(10)



Other Automotive Connector Accessories(6)

## Customers Also Bought



TE Part #8-34161-1  
TERMINAL,PG R 16-14 10



TE Part #8-34149-1  
PG R 22-16 COMM 22-18 MIL 10



TE Part #8-33463-1  
TERMINAL,SOLIS R 8 3/8



TE Part #8-34854-1  
TERMINAL,PG R 12-10 10



TE Part #55678-1  
TERM,PG RING 12-10 1/4



TE Part #2-31808-2  
TERMINAL, SOLIS R 8 5/16



 
TE Part #8-34160-1  
TERMINAL,PG R 16-14 8



TE Part #8-34162-1  
TERMINAL,PG R 16-14 1/4



TE Part #G-NSDOG1-006  
AXISENSE-1 V-OUT-180 TILT SENSOR



TE Part #1719826-2  
SINGLE WIRE SEAL,8MM HV

## Documents



### Product Drawings

[SEALING PLUG, SIZE 12, KEYING, YEL](#)

English

---

### CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG\\_CVM\\_CVM\\_0413-214-1205\\_A.2d\\_dxf.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_0413-214-1205\\_A.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_0413-214-1205\\_A.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

---

### Datasheets & Catalog Pages

[DEUTSCH HD30 & HDP20 CONNECTOR SERIES](#)

English

[CONNECTOR SELECTOR](#)

English

---

### Product Specifications

[Application Specification](#)

English

---

### Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English